




Cavity Plugs

Material:
Steel, zinc-plated


2-WAY CAVITY

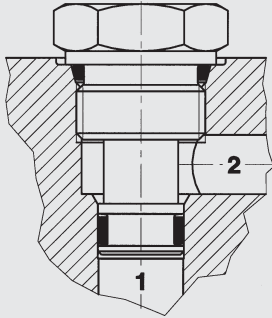


SYMBOLS




3-WAY CAVITY

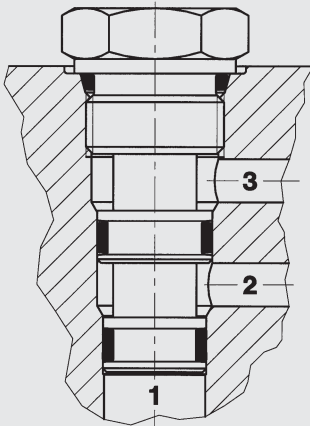


SYMBOLS

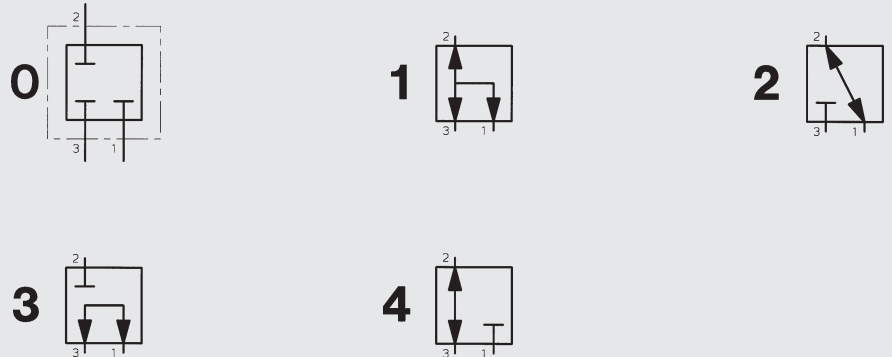

4-WAY CAVITY

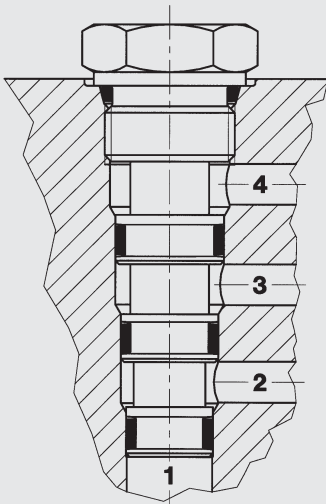

SYMBOLS

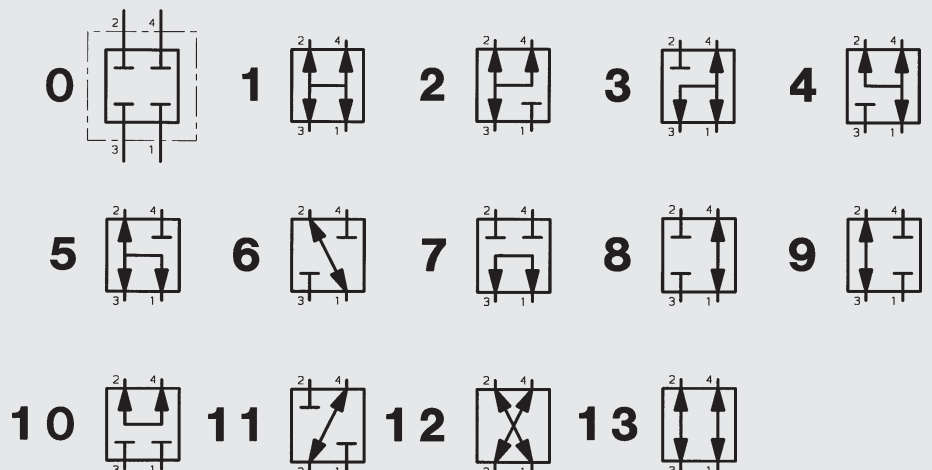

ORDERING INFORMATION

FP 08 2 - 0 - N

Cavity Size

- 08 (SAE8)
- 10 (SAE10)
- 12 (SAE12)
- 16 (SAE16)

Cavity Type

- 1 = all ports connected (2-, 3- and 4-Way)
- 2 = 2-Way
- 3 = 3-Way
- 4 = 4-Way

Symbol

0, 1, 2, 3, 4, 5, 6, 7, 8, 9, 10, 11, 12, 13

Seals

- N = NBR (standard)
- V = FKM (optional)

STANDARD PLUGS

	Code	Part No.
2-Way	FP082-0-N	3012753
	FP102-0-N	3014157
	FP122-0-N	3064028
	FP162-0-N	3056431
3-Way	FP083-0-N	3012754
	FP103-0-N	3014158
	FP123-0-N	3082862
	FP163-0-N	3056433
4-Way	FP084-0-N	3012756
	FP104-0-N	3014159
	FP124-0-N	3082863
	FP164-0-N	3082864
2-, 3- and 4-Way (Symbol 1)	FP081-1-N	3012752
	FP101-1-N	3014156
	FP121-1-N	3064381
	FP161-1-N	3056429

NOTE

The information in this brochure relates to the operating conditions and applications described.

For applications or operating conditions not described, please contact the relevant technical department.

Subject to technical modifications.

HYDAC Fluidtechnik GmbH

Justus-von-Liebig-Str.

D-66280 Sulzbach/Saar

Tel: 0 68 97 /509-01

Telefax: 0 68 97 /509-598

E-Mail: flutec@hydac.com