



HY-LOOP hook-and-loop strap CFL HLB

Model code
(also order example)

CFL **HLB** **W20** **L200** **PA/PU**

Series

CFL = HY-LOOP hook-and-loop clamp

Designation

HLB = hook-and-loop strap

Strap width

W20 = 20 mm

Length

(according to dimensions)

Material

PA/PU = polyamide/polyurethane


ATTENTION

The HY-LOOP hook-and-loop strap is used to fasten pipes and cables but does not serve to transfer loads.

Technical data

| | |
|------------------|---|
| Material, eyelet | Polyamide |
| Material, strap | Polyurethane Free from halogens and silicone |
| Service life | > 50% holding force after 100 cycles |
| Melting point | 150 °C |
| Width | 20 mm |
| Length | (According to dimensions) |
| Colour | Black |

Dimensions [in mm]

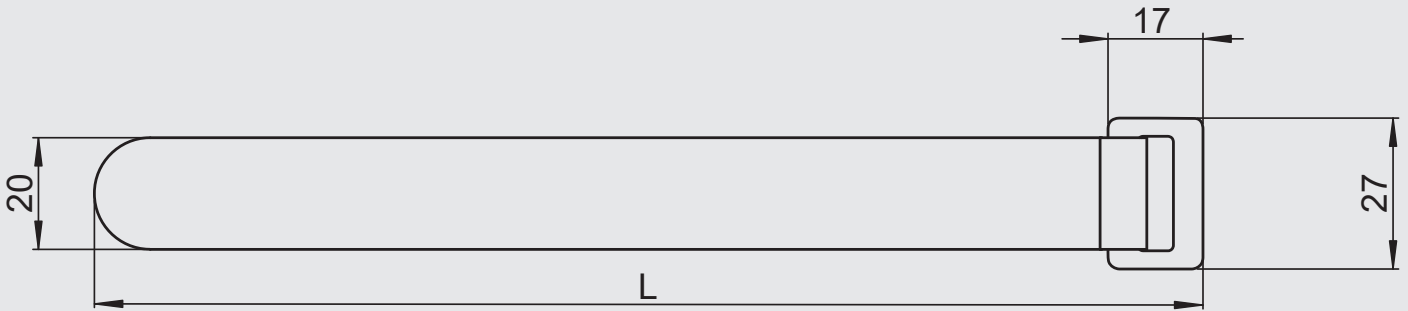

| Designation | Part no. | L [mm] |
|------------------------|----------|-----------|
| CFL HLB W20 L170 PA/PU | 4512830 | 170 |
| CFL HLB W20 L200 PA/PU | 4512832 | 200 |
| CFL HLB W20 L300 PA/PU | 4512833 | 300 |
| CFL HLB W20 L400 PA/PU | 4512834 | 400 |
| CFL HLB W20 L500 PA/PU | 4512837 | 500 |
| CFL HLB W20 L600 PA/PU | 4512840 | 600 |

NOTE

The information in this brochure relates to the operating conditions and applications described. For applications or operating conditions not described please contact the relevant technical department.

The operator is always responsible for determining the product suitability for the specific application. Quantified values for product characteristics are average values for a new product that undergo a time deterioration process.

Subject to technical modifications and errors.

HYDAC Accessories GmbH

Hirschbachstr. 2

66280 Sulzbach/Saar

Tel.: +49 (0)6897 - 509-01

Internet: www.hydac.com

E-mail: accessories@hydac.com